


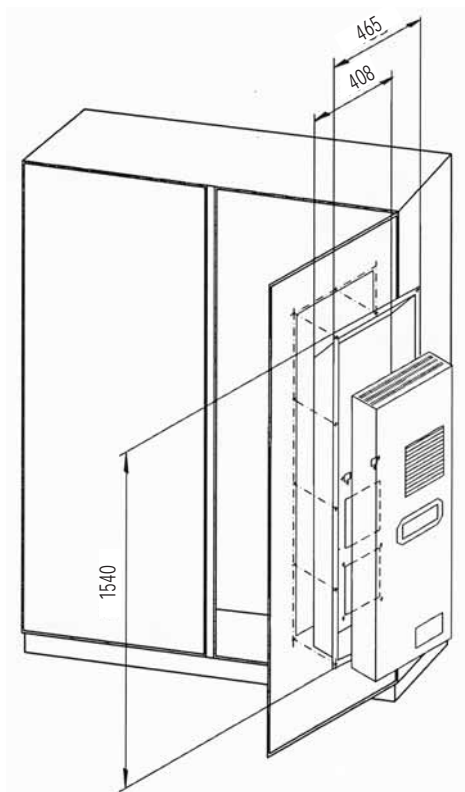


Built-in frames DTZ

... allows you to recess our cooling units.



Installation cutout

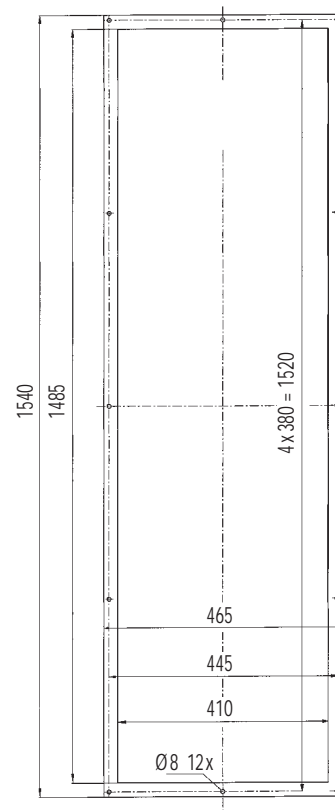

Technical data:	DTZ 080	DTZ 100	DTZ 120	DTZ 140	DTZ 080LF/41	DTZ 100LF/41	DTZ 120LF/41	DTZ 140LF/41
Models	DTS 7201; DTS 7301				DTS 7141; DTS 7241; DTS 7341; DTS 7441; DTS 7541			
Installation	80 mm	100 mm	120 mm	140 mm	80 mm	100 mm	120 mm	140 mm
Height	1540 mm							
Width	465 mm							
Fixing flange	28,5 mm							
Orientation	vertical							
Construction material	sheet steel							
Anti-corrosion protection	electrostatically powder-coated (200 °C)							
Colour	RAL 7032 (European grey), other colours available on request							
Standard scope of supply	sealing material, cutout template, instruction sheet				sealing material, cutout template, instruction sheet, bend for condensate drain			
System of protection	IP 54 against the enclosure (DIN EN 60529) when used as recommended							