



Cooling capacity performance curves
PFB 42.500 IP 54

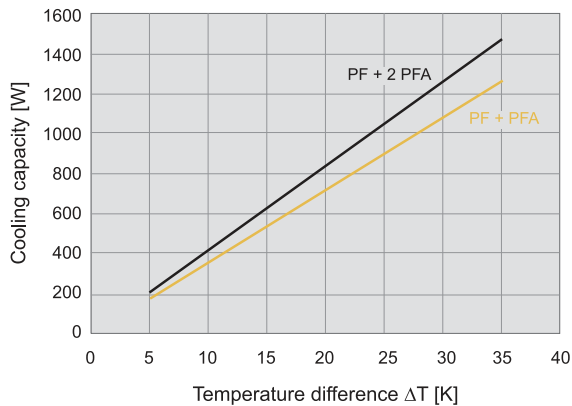


Static pressure performance curves
PFB 42.500 IP 54

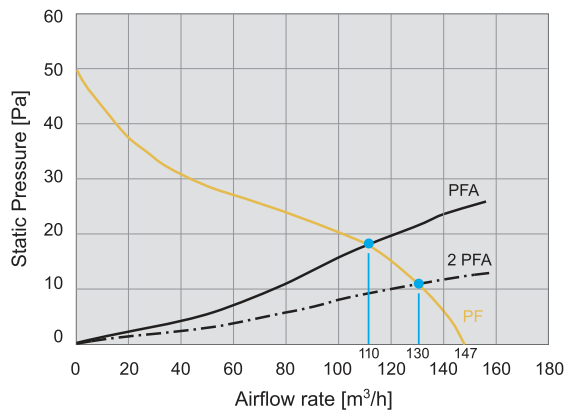

Dimensions

mm	PFB 42.500	PFBA 40.000
X	252	252
Y	252	252
Z1	6	6
Z2	97	38
A ¹	223	223
B ¹	223	223

¹ for material thicknesses up to 2 mm
+1 mm for thickness of material > 2 mm ≤ 3 mm

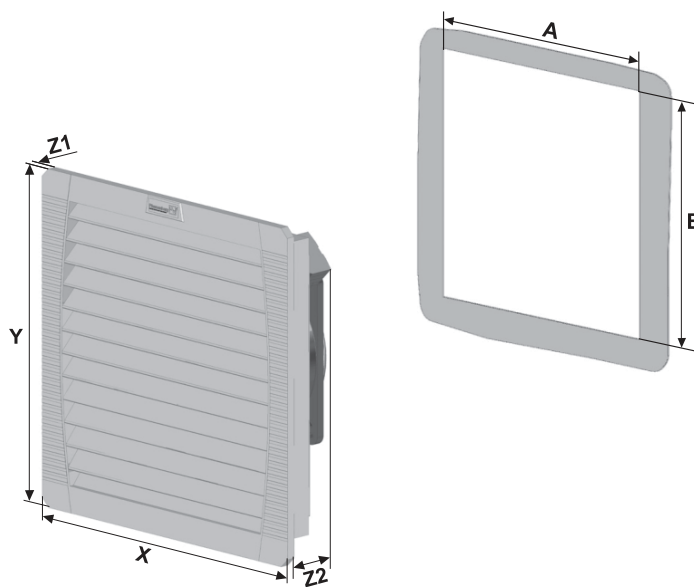

IP 55 Filter fans available on request