



# Accessories

## SOFT START MODULE

The module enables the soft start and limitation of the large initial current peaks of capacitive consumers. This includes all DC devices with a smoothing capacitor on the voltage input, regardless of whether the devices are sounders or flashing lights. The SSM Soft Start Module prevents the overloading of the relay contacts when switching on and the premature triggering of overcurrent circuit breakers (e.g. PLC controller). The module is available as a built-in housing for DIN rail mounting or is already integrated in various devices.

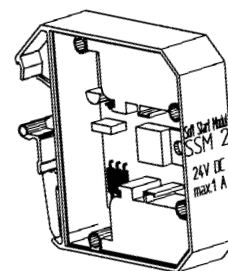

PRODUCT	SSM2
ARTICLE NO.	4100000500
DATA	
Operating range	18–30 V
	DC
Nominal current consumption	1 A
Suitable for ...	DC devices
Operating temperature	–40 ... +50 °C
Storage temperature	–40 ... +70 °C
Relative humidity	90 %

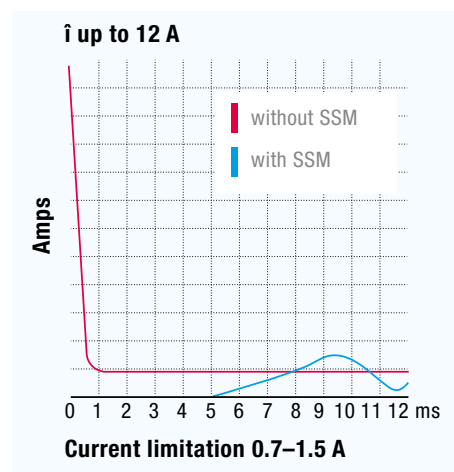

## LIGHT SOURCES

Filament lamps for Pfannenberg lights with socket.



PRODUCT	SUITABLE FOR ...	RATED VOLTAGE	ARTICLE NO.
Filament lamp E14 15 W	PD   P 350 TSB   P 450 TDB	24 V	28113000000
Filament lamp E14 15 W	PD   P 350 TSB   P 450 TDB	12 V	28113000001
Filament lamp E14 15 W	PD   P 350 TSB   P 450 TDB	48 V	28113000002
Filament lamp E14 15 W	PD   P 350 TSB   P 450 TDB	110 V	28113000003
Filament lamp E14 15 W	PD   P 350 TSB   P 450 TDB	240 V	28113000004
Filament lamp E27 25 W	P 450 TSB	24 V	28113000019
Filament lamp E27 25 W	P 450 TSB	115 V	28113000020
Filament lamp E27 25 W	P 450 TSB	230 V	28113000021
Halogen lamp G6.35/GY6.35 20 W	P 300 RTH	12 V	28113000027
Halogen lamp G6.35/GY6.35 20 W	P 300 RTH	24 V	28113000028
Halogen lamp G6.35/GY6.35 25 W	P 300 RTH	115 V	28113000029
Halogen lamp G6.35/GY6.35 25 W	P 300 RTH	230 V	28113000030
Halogen lamp G6.35/GY6.35 35 W	P 400 RTH	12 V	28113000031
Halogen lamp G6.35/GY6.35 35 W	P 400 RTH	24 V	28113000032
Halogen lamp G6.35/GY6.35 40 W	P 400 RTH	115 V	28113000033
Halogen lamp G6.35/GY6.35 40 W	P 400 RTH	230 V	28113000034